

Motors

Automation

Energy

Transmission and
Distribution

Coatings

UBW

Molded-Case Circuit Breaker
UL 489 Listed



Driving efficiency and sustainability



UBW


Molded-Case Circuit Breaker
UL 489 Listed

UL File No. E310329

The WEG UBW Series of Molded Case Circuit Breakers are designed to provide short circuit and thermal protection for industrial electrical equipment. Increased frame sizes and amperages cover more applications and when combined with our complete line of Automation/Control products, provide customers a one stop shop for all their panel needs. The UBW product line ranges from 15A to 2500A and SCCR ratings for 35-100 KAIC to meet more of your application requirements. The UBW line offers the quality, reliability and uncompromising protection that you have come to expect from WEG.

Standard Features:

- Broad product offering up to 2500 Amps
- Multiple SCCR Ratings up to 100 KIAC Ratings
- Maintenance mode for superior Arc Flash Protection
- Field or Factory installed options
- Optional multi-conductor load side lugs

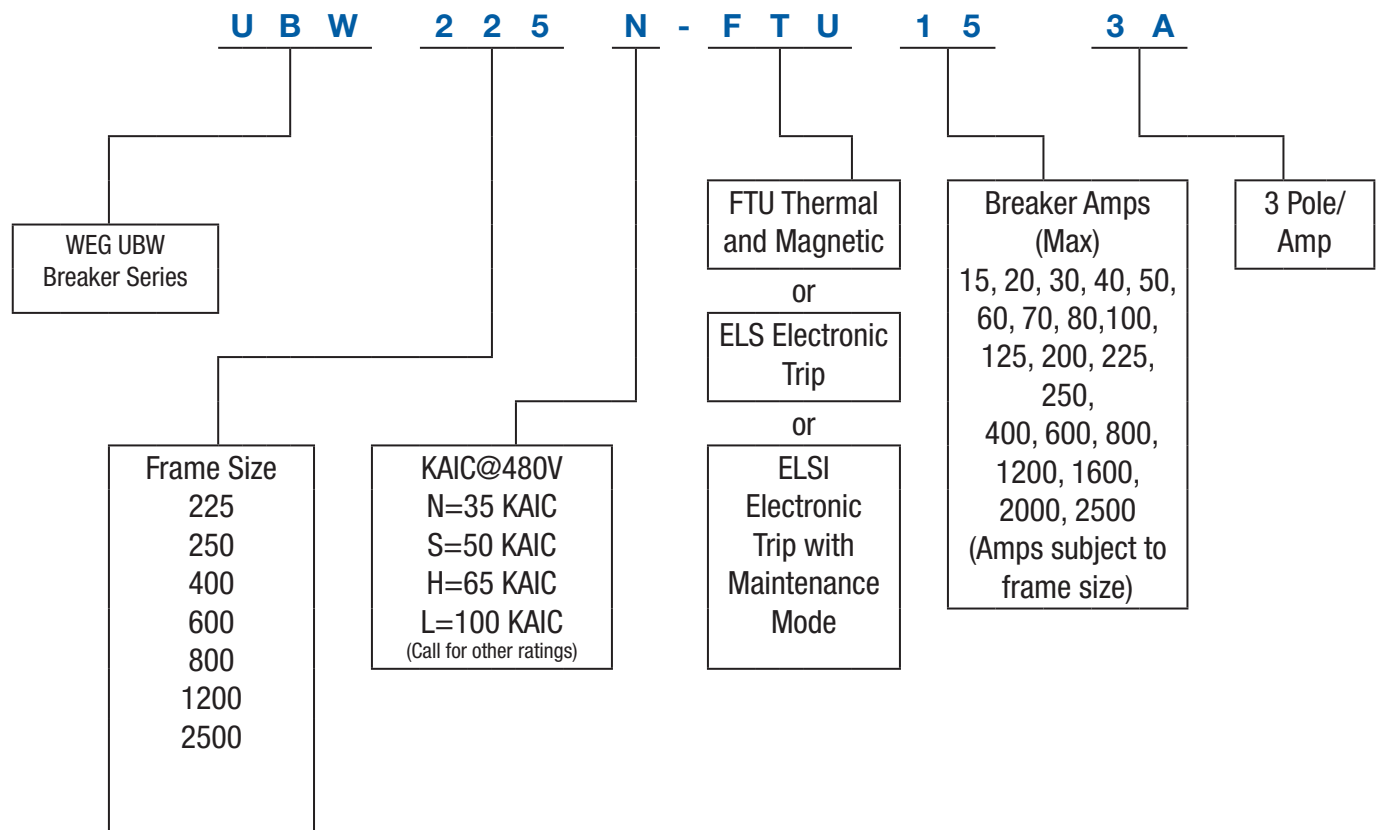

*If ordering with factory installed options replace 3A with alpha numeric option code sequence



UBW225 Frame - Line and load side lugs included

Thermal Setting	Short Circuit Interrupting Capacity		Catalog Number	List Price	Multiplier
(A)	480VAC	600VAC			
15	35kA	18kA	UBW225N-FTU15-3A	\$665	Z10
20			UBW225N-FTU20-3A	\$665	Z10
30			UBW225N-FTU30-3A	\$665	Z10
40			UBW225N-FTU40-3A	\$665	Z10
50			UBW225N-FTU50-3A	\$665	Z10
60			UBW225N-FTU60-3A	\$665	Z10
70			UBW225N-FTU70-3A	\$665	Z10
80			UBW225N-FTU80-3A	\$728	Z10
100			UBW225N-FTU100-3A	\$728	Z10
125			UBW225N-FTU125-3A	\$1,100	Z10
150			UBW225N-FTU150-3A	\$1,550	Z10
200			UBW225N-FTU200-3A	\$1,550	Z10
225			UBW225N-FTU225-3A	\$1,550	Z10
15	65kA	25kA	UBW225H-FTU15-3A	\$965	Z10
20			UBW225H-FTU20-3A	\$965	Z10
30			UBW225H-FTU30-3A	\$965	Z10
40			UBW225H-FTU40-3A	\$965	Z10
50			UBW225H-FTU50-3A	\$965	Z10
60			UBW225H-FTU60-3A	\$965	Z10
70			UBW225H-FTU70-3A	\$965	Z10
80			UBW225H-FTU80-3A	\$1,055	Z10
100			UBW225H-FTU100-3A	\$1,055	Z10
125			UBW225H-FTU125-3A	\$1,450	Z10
150			UBW225H-FTU150-3A	\$2,050	Z10
200			UBW225H-FTU200-3A	\$2,050	Z10
225			UBW225H-FTU225-3A	\$2,050	Z10
15	100kA	35kA	UBW225L-FTU15-3A	\$1,200	Z10
20			UBW225L-FTU20-3A	\$1,200	Z10
30			UBW225L-FTU30-3A	\$1,200	Z10
40			UBW225L-FTU40-3A	\$1,200	Z10
50			UBW225L-FTU50-3A	\$1,200	Z10
60			UBW225L-FTU60-3A	\$1,200	Z10
70			UBW225L-FTU70-3A	\$1,200	Z10
80			UBW225L-FTU80-3A	\$1,200	Z10
100			UBW225L-FTU100-3A	\$1,350	Z10
125			UBW225L-FTU125-3A	\$1,350	Z10
150			UBW225L-FTU150-3A	\$2,800	Z10
200			UBW225L-FTU200-3A	\$2,400	Z10
225			UBW225L-FTU225-3A	\$2,400	Z10

UBW

UBW 250 400 600 800 Frame- - Line and load side lugs included



Frame 250

Thermal Setting	KA Rating at 480VAC	Catalog Number	List Price	Multiplier
250	35	UBW250N-FTU250-3A	\$1,550	Z10
250	65	UBW250H-FTU250-3A	\$2,050	Z10
250	100	UBW250L-FTU250-3A	\$2,400	Z10

Frame 400

300	35	UBW400N-FTU300-3A	\$3,000	Z10
400	35	UBW400N-FTU400-3A	\$3,000	Z10
300	65	UBW400H-FTU300-3A	\$3,700	Z10
400	65	UBW400H-FTU400-3A	\$3,700	Z10
300	100	UBW400L-FTU300-3A	\$4,700	Z10
400	100	UBW400L-FTU400-3A	\$4,700	Z10

Frame 600

500	35	UBW600N-FTU500-3A	\$5,000	Z10
600	35	UBW600N-FTU600-3A	\$5,000	Z10
500	65	UBW500H-FTU500-3A	\$7,000	Z10
600	65	UBW600H-FTU600-3A	\$7,000	Z10
500	100	UBW500L-FTU500-3A	\$8,300	Z10
600	100	UBW600L-FTU600-3A	\$8,300	Z10

Frame 800

800	50	UBW800S-FTU800-3A	\$6,000	Z10
800	65	UBW800H-FTU800-3A	\$8,000	Z10

Frame 1200 with Electronic Trip - Not supplied with lugs

800	50	UBW1200S-ELS800-3A	\$14,000.00	Z10
800	65	UBW1200H-ELS800-3A	\$17,950.00	Z10
800	100	UBW1200L-ELS800-3A	\$21,950.00	Z10
1200	50	UBW1200S-ELS1200-3A	\$21,300.00	Z10
1200	65	UBW1200H-ELS1200-3A	\$22,200.00	Z10
1200	100	UBW1200L-ELS1200-3A	\$23,500.00	Z10

Frame 1200 with Electronic Trip and Maintenance Mode - Not supplied with lugs

800	50	UBW1200S-ELSI800-3A	\$21,950.00	Z10
800	65	UBW1200H-ELSI800-3A	\$21,950.00	Z10
800	100	UBW1200L-ELSI800-3A	\$24,600.00	Z10
1200	50	UBW1200S-ELSI1200-3A	\$22,000.00	Z10
1200	65	UBW1200H-ELSI1200-3A	\$24,500.00	Z10
1200	100	UBW1200L-ELSI1200-3A	\$25,800.00	Z10

UBW 2500 Frame



Frame 2500 with Electronic Trip - not supplied with lugs

Thermal Setting	KA Raing 480vac	Catalog Number	List	Multiplier
1600	65	UBW2500H-ELS1600-3A	\$29,600	Z10
1600	100	UBW2500L-ELS1600-3A	\$32,200	Z10
2000	65	UBW2500H-ELS2000-3A	\$30,700	Z10
2000	100	UBW2500L-ELS2000-3A	\$33,300	Z10
2500	65	UBW2500H-ELS2500-3A	\$32,400	Z10
2500	100	UBW2500L-ELS2500-3A	\$35,200	Z10

Frame 2500 with Electronic Trip and Maintenance Mode

Thermal Setting	KA Raing 480vac	Catalog Number	List	Multiplier
1600	65	UBW2500H-ELSI1600-3A	\$32,300	Z10
1600	100	UBW2500L-ELSI1600-3A	\$34,900	Z10
2000	65	UBW2500H-ELSI2000-3A	\$33,300	Z10
2000	100	UBW2500L-ELSI2000-3A	\$36,000	Z10
2500	65	UBW2500H-ELSI2500-3A	\$35,000	Z10
2500	100	UBW2500L-ELSI2500-3A	\$37,900	Z10

UBW

UBW Breaker Accessories

225 Frame Factory Installed only

How to order - Example

		\$965 + \$699.50 = \$1664.50	Use Z10 Multiplier	
UBW225H-FTU25-3A List \$965.00	AX-UBW225 List \$699.50			
Code	WEG Catalog Number	Description	List	Multiplier
A1	AX UBW225	AUXILIARY SWITCH	\$699.05	Z10
A2	AL UBW225	ALARM SWITCH	\$699.05	
A3	AXAL UBW225	AUX/ALARM SWITCH	\$782.00	
S	SHT UBW225 E59	SHUNT TRIP 12-24AC/DC	\$787.14	
SS	SHT UBW225 E58	SHUNT TRIP 48-120AC/48-60DC	\$787.14	
S0	SHT UBW225 E62	SHUNT TRIP 208-380AC/110-127DC	\$787.14	
11	UVT UBW225 C03	UNDERVOLTAGE RELEASE 24DC	\$787.14	
12	UVT UBW225 D60	UNDERVOLTAGE RELEASE 110-125AC	\$787.14	
13	UVT UBW225 D96	UNDERVOLTAGE RELEASE 208-240AC	\$787.14	
	UVT UBW1200 D96	UNDERVOLTAGE RELEASE 208-240AC	\$964.29	\$150.00

250-2500 Frame with Options

How to order - Example

			List Prices Totalled	Apply Z10 Multiplier for Final Price
UBW250 - 2500 Frame List \$	AX-UBW250 - 2500 List \$	Installation Charge List \$		

UBW250 Frame Options

Code	WEG Catalog Number	Description	List	Install List	Multiplier
A1	AX UBW250	AUXILIARY SWITCH	\$445.71	\$350.00	Z10
A2	AL UBW250	ALARM SWITCH	\$445.71	\$350.00	
A3	AXAL UBW250	AUX/ALARM SWITCH	\$527.14	\$350.00	
S1	SHT UBW250 E59	SHUNT TRIP 12-24AC/DC	\$587.14	\$350.00	
S2	SHT UBW250 E61	SHUNT TRIP 100-240AC/110-125DC	\$587.14	\$350.00	
21	UVT UBW250 C03	UNDERVOLTAGE RELEASE 24DC	\$587.14	\$350.00	
22	UVT UBW250 D60	UNDERVOLTAGE RELEASE 110-125AC	\$587.14	\$350.00	
23	UVT UBW250 D96	UNDERVOLTAGE RELEASE 208-240AC	\$587.14	\$350.00	

UBW400 Frame Options - See above for How to Order

Code	WEG Catalog Number	Description	List	Install List	Multiplier
A1	AX UBW400	AUXILIARY SWITCH	\$557.41	\$350.00	Z10
A2	AL UBW400	ALARM SWITCH	\$557.41	\$350.00	
A3	AXAL UBW400	AUX/ALARM SWITCH	\$628.29	\$350.00	
S1	SHT UBW400 E59	SHUNT TRIP 12-24AC/DC	\$627.43	\$350.00	
S2	SHT UBW400 E61	SHUNT TRIP 100-240AC/110-125DC	\$627.43	\$350.00	
21	UVT UBW400 C03	UNDERVOLTAGE RELEASE 24DC	\$627.43	\$350.00	
22	UVT UBW400 D60	UNDERVOLTAGE RELEASE 110-125AC	\$627.43	\$350.00	
23	UVT UBW400 D96	UNDERVOLTAGE RELEASE 208-240AC	\$627.43	\$350.00	

UBW800 Frame Options - See Previous Page for How to Order

Code	WEG Catalog Number	Description	List	Install List	Multiplier
A1	AX UBW800^	AUXILIARY SWITCH	\$698.67	\$450.00	Z10
A2	AL UBW800^	ALARM SWITCH	\$698.67	\$450.00	
A3	AXAL UBW800^	AUX/ALARM SWITCH	\$772.29	\$450.00	
S5	SHT UBW800 E60^	SHUNT TRIP 9-24AC/12-24DC	\$873.24	\$450.00	
S6	SHT UBW8000 D95^	SHUNT TRIP 100-240AC	\$873.24	\$450.00	
41	UVT UBW800 C03^	UNDERVOLTAGE RELEASE 24DC	\$873.24	\$450.00	
42	UVT UBW80 D60^	UNDERVOLTAGE RELEASE 110-127AC	\$873.24	\$450.00	
43	UVT UBW800 D96^	UNDERVOLTAGE RELEASE 208-240AC	\$873.24	\$450.00	

UBW1200 Frame Options - See Previous Page for How to Order

Code	WEG Catalog Number	Description	List	Install List	Multiplier
A1	AX UBW1200	AUXILIARY SWITCH	\$771.43	\$650.00	Z10
A2	AL UBW1200	ALARM SWITCH	\$771.43	\$650.00	
A3	AXAL UBW1200	AUX/ALARM SWITCH	\$865.71	\$650.00	
S7	SHT UBW1200 E60	SHUNT TRIP 9-24AC/12-24DC	\$964.29	\$650.00	
S8	SHT UBW1200 D95	SHUNT TRIP 100-240AC	\$964.29	\$650.00	
51	UVT UBW1200 C03	UNDERVOLTAGE RELEASE 24DC	\$964.29	\$650.00	
52	UVT UBW1200 D60	UNDERVOLTAGE RELEASE 110-127AC	\$964.29	\$650.00	
53	UVT UBW1200 D96	UNDERVOLTAGE RELEASE 208-240AC	\$964.29	\$650.00	

UBW2500 Frame Options - See Previous Page for How to Order

Code	WEG Catalog Number	Description	List	Install List	Multiplier
A1	AX UBW2500	AUXILIARY SWITCH	\$1,034.19	\$650.00	Z10
A2	AL UBW2500	ALARM SWITCH	\$1,034.19	\$650.00	
S9	SHT UBW2500 E26	SHUNT TRIP 24AC/DC	\$1,157.14	\$650.00	
S10	SHT UBW1200 D95	SHUNT TRIP 100-240AC	\$1,157.14	\$650.00	
61	UVT UBW2500 C03	UNDERVOLTAGE RELEASE 24DC	\$1,157.14	\$650.00	
62	UVT UBW2500 D60	UNDERVOLTAGE RELEASE 110-127AC	\$1,157.14	\$650.00	
63	UVT UBW2500 D96	UNDERVOLTAGE RELEASE 208-240AC	\$1,157.14	\$650.00	

UBW

Lugs

All WEG UBW Circuit Breaker supplied with Line/Load Lugs



Standard Lugs

Frame	Part Number	Conductor Count	Wire Size/Range	Lugs Count	List	Multiplier
225	LT3-UBW225	1	14-4/0 AWG	3	\$274.29	Z10
250	LT1-UBW250	1	4-350	1	\$73.09	Z10
400	LT3-UBW400	2	3/0-250	3	\$196.57	Z10
400	LT1-UBW400	1	250-500	1	\$65.52	Z10
400	LT3D-UBW400	1	400-500	3	\$252.95	Z10
600	LT3-UBW600	2	4/0-600	3	\$310.86	Z10

Multi-Wire Lugs (Load Side Only)

Frame	Part Number	Conductor Count	Wire Size/Range	Lugs Count	List	Multiplier
225	WT3-UBW225	3	14-2	1	\$212.10	Z10
225	WT6-UBW225	6	14-6	1	\$212.10	Z10
250	WT3-UBW250	3	14-2	1	\$370.76	Z10
250	WT6-UBW250	6	14-6	1	\$370.76	Z10
400	WT3-UBW400	3	12-2/0	1	\$382.29	Z10
400	WT6-UBW400	6	14-3	1	\$382.29	Z10
600	LT1D-UBW450	2	4-4/0	1	\$156.95	Z10
800	LT1A2-UBW800	3	3/0-400	1	\$172.19	Z10
800	LT1A1-UBW700	2	1-500	1	\$126.48	Z10
800	LT1A-UBW800	2	500-750 KCMIL	1	\$219.63	Z10
1200	LT1B2-UBW700	2	1-500	1	\$121.50	Z10
1200	LT1B3-UBW1000	3	3/0-400	1	\$163.79	Z10
1200	LT1B4-UBW1200	4	4/0-500	1	\$230.14	Z10
2500	LT1B3-UBW1200	2	1-500	1	\$243.00	Z10
2500	LT1A-UBW1600	4	500-1000	1	\$333.71	Z10
2500	LT1C-UBW1600	4	1-600	1	\$530.29	Z10
2500	RT1-UBW2000	4	1-600	1	\$299.57	Z10
2500	RT1-UBW2500	6	2-600	1	\$641.14	Z10

** Metric Mounting Hardware



Handle/Mechanism/Shafts NEMA 1/3R/12

Part Number	Description	List	Multiplier
EHC6-UBW225	Handle + Mechanism + Shaft 6"	\$372.86	Z10
EHC12-UBW225	Handle + Mechanism + Shaft 12"	\$384.29	Z10
EHC16-UBW225	Handle + Mechanism + Shaft 16"	\$410.00	Z10
EHC24-UBW225	Handle + Mechanism + Shaft 24"	\$437.33	Z10
EHC6-UBW250	Handle + Mechanism + Shaft 6"	\$385.71	Z10
EHC12-UBW250	Handle + Mechanism + Shaft 12"	\$397.24	Z10
EHC16-UBW250	Handle + Mechanism + Shaft 16"	\$497.90	Z10
EHC24-UBW250	Handle + Mechanism + Shaft 24"	\$517.43	Z10
EHC6-UBW400	Handle + Mechanism + Shaft 6"	\$393.33	Z10
EHC12-UBW400	Handle + Mechanism + Shaft 12"	\$407.71	Z10
EHC16-UBW400	Handle + Mechanism + Shaft 16"	\$482.29	Z10
EHC24-UBW400	Handle + Mechanism + Shaft 24"	\$530.95	Z10
EHC6-UBW800^	Handle + Mechanism + Shaft 6"	\$544.76	Z10
EHC12-UBW800^	Handle + Mechanism + Shaft 12"	\$557.05	Z10
EHC16-UBW800^	Handle + Mechanism + Shaft 16"	\$650.19	Z10
EHC24-UBW800^	Handle + Mechanism + Shaft 24"	\$679.43	Z10
EHG6-UBW1200	Handle + Mechanism + Shaft 6"	\$656.33	Z10
EHG12-UBW1200	Handle + Mechanism + Shaft 12"	\$573.05	Z10
EHG16-UBW1200	Handle + Mechanism + Shaft 16"	\$679.43	Z10
EHG24-UBW1200	Handle + Mechanism + Shaft 24"	\$709.76	Z10

^ For both UBW600 and UBW800 products

Note: UBW 2500 utilizes flange mount mechanism only. Rotary handle is not available.

UBW

Handle/Mechanism/Shafts NEMA 4/4X

Part Number	Description	List	Multiplier
EHC6X-UBW225	Handle + Mechanism + Shaft 6"	\$468.57	Z10
EHC12X-UBW225	Handle + Mechanism + Shaft 12"	\$482.29	Z10
EHC16X-UBW225	Handle + Mechanism + Shaft 16"	\$536.95	Z10
EHC24X-UBW225	Handle + Mechanism + Shaft 24"	\$548.67	Z10
EHC6X-UBW250	Handle + Mechanism + Shaft 6"	\$548.67	Z10
EHC12X-UBW250	Handle + Mechanism + Shaft 12"	\$577.90	Z10
EHC16X-UBW250	Handle + Mechanism + Shaft 16"	\$613.05	Z10
EHC24X-UBW250	Handle + Mechanism + Shaft 24"	\$634.57	Z10
EHC6X-UBW400	Handle + Mechanism + Shaft 6"	\$549.67	Z10
EHC12X-UBW400	Handle + Mechanism + Shaft 12"	\$587.43	Z10
EHC16X-UBW400	Handle + Mechanism + Shaft 16"	\$622.57	Z10
EHC24X-UBW400	Handle + Mechanism + Shaft 24"	\$644.10	Z10
EHC6X-UBW800^	Handle + Mechanism + Shaft 6"	\$736.10	Z10
EHC12X-UBW800^	Handle + Mechanism + Shaft 12"	\$765.33	Z10
EHC16X-UBW800^	Handle + Mechanism + Shaft 16"	\$804.38	Z10
EHC24X-UBW800^	Handle + Mechanism + Shaft 24"	\$804.38	Z10
EHG6X-UBW1200	Handle + Mechanism + Shaft 6"	\$765.33	Z10
EHG12X-UBW1200	Handle + Mechanism + Shaft 12"	\$784.86	Z10
EHG16X-UBW1200	Handle + Mechanism + Shaft 16"	\$833.71	Z10
EHG24X-UBW1200	Handle + Mechanism + Shaft 24"	\$833.71	Z10

Note: UBW 2500 utilizes flange mount mechanism only. Rotary handle is not available.

^ For both UBW600 and UBW800 products



Flange Handle 1/3R/12

Part Number	Description	List	Multiplier
FHP3-UBW225	Flexible Shaft 3' Cable	\$871.11	Z10
FHP5-UBW225	Flexible Shaft 5' Cable	\$906.67	Z10
FHP6-UBW225	Flexible Shaft 6' Cable	\$933.33	Z10
FHP3-UBW250	Flexible Shaft 3' Cable	\$1,022.22	Z10
FHP5-UBW250	Flexible Shaft 5' Cable	\$1,056.00	Z10
FHP6-UBW250	Flexible Shaft 6' Cable	\$1,073.60	Z10
FHP3-UBW400	Flexible Shaft 3' Cable	\$1,102.22	Z10
FHP5-UBW400	Flexible Shaft 5' Cable	\$1,144.00	Z10
FHP6-UBW400	Flexible Shaft 6' Cable	\$1,160.44	Z10
FHP5-UBW800[^]	Flexible Shaft 5' Cable	\$1,379.92	Z10
FHP6-UBW800[^]	Flexible Shaft 6' Cable	\$1,442.04	Z10
FHP5-UBW1200	Flexible Shaft 5' Cable	\$1,426.76	Z10
FHP6-UBW1200	Flexible Shaft 6' Cable	\$1,591.11	Z10
FHP5-UBW2500	Flexible Shaft 5' Cable	\$1,608.62	Z10
FHP6-UBW2500	Flexible Shaft 6' Cable	\$1,648.71	Z10

[^] For both UBW600 and UBW800 products

Flange Handle 4/4X

Part Number	Description	List	Multiplier
FHP3X-UBW225	Flexible Shaft 3' Cable	\$945.78	Z10
FHP5X-UBW225	Flexible Shaft 5' Cable	\$1,057.76	Z10
FHP6X-UBW225	Flexible Shaft 6' Cable	\$1,070.22	Z10
FHP3X-UBW250	Flexible Shaft 3' Cable	\$1,141.07	Z10
FHP5X-UBW250	Flexible Shaft 5' Cable	\$1,186.04	Z10
FHP6X-UBW250	Flexible Shaft 6' Cable	\$1,191.47	Z10
FHP3X-UBW400	Flexible Shaft 3' Cable	\$1,228.71	Z10
FHP5X-UBW400	Flexible Shaft 5' Cable	\$1,259.28	Z10
FHP6X-UBW400	Flexible Shaft 6' Cable	\$1,264.89	Z10
FHP5X-UBW800[^]	Flexible Shaft 5' Cable	\$1,508.00	Z10
FHP6X-UBW800[^]	Flexible Shaft 6' Cable	\$1,536.44	Z10
FHP5X-UBW1200	Flexible Shaft 5' Cable	\$1,608.71	Z10
FHP6X-UBW1200	Flexible Shaft 6' Cable	\$1,626.22	Z10
FHP5X-UBW2500	Flexible Shaft 5' Cable	\$1,720.44	Z10
FHP6X-UBW2500	Flexible Shaft 6' Cable	\$1,763.11	Z10

[^] For both UBW600 and UBW800 products

UBW

WEG – On/Off Locking Mechanisms

Frame	Part Number	Padlock Style	List
225	HL-UBW225	HASP	\$106.76
250/400	HL-UBW400	HASP	\$118.19
600	PL-UBW600	HASP	\$173.24
800	PL-UBW800	HASP	\$188.43
1200	HL-UBW1200	HASP	\$229.00
2500	PL-UBW2500	HASP	\$314.10



WEG Padlock - PL and HL

Direct Mount Handle

Frame	Part Number	List
225	DHI-UBW225	\$321.43
400	DHI-UBW400	\$347.14
600 (500/600AMP)	DHI-UBW600	\$330.00
800/800AMP	DHI-UBW600	\$330.00
800/800AMP	EDHI-UBW800	\$53.81
1200	EDHI-1200	\$78.10
2500	EDHI-2500	\$104.10



EDHI Style



DHI Style

Frame Size	225	250	400	600	800	1200	2500
Rated Current - In 40° C	15,20,30,40,50,60,70,80,100,125,200,225	250	300,400	500,600	800	800,1200	1600,2000,2500
No.Of Poles	3	3	3	3	3	3	3
Rated operational Voltage-Ue	600	600	600	600	600	600	600
Max Options	2*	2**	2**	2**	2**	2**	3***
Reference standard	UL489	UL489	UL489	UL489	UL489	UL489	UL489

*Factory Installed Only ** 1 Option-Right, 1 Option Left *** All Options Right Side Only

UL interrupting rating- Icu		N	H	L
Frame 225	120VAC	65kA	100kA	200kA
	240VAC	65kA	100kA	200kA
	480VAC	35kA	65kA	100kA
	600VAC	18kA	25kA	35kA
Frame 250	120VAC	65kA	100kA	200kA
	240VAC	65kA	100kA	200kA
	480VAC	35kA	65kA	100kA
	600VAC	18kA	25kA	35kA
Frame 400	120VAC	65kA	100kA	200kA
	240VAC	65kA	100kA	200kA
	480VAC	35kA	65kA	100kA
	600VAC	25kA	35kA	65kA
Frame 600	120VAC	65kA	100kA	200kA
	240VAC	65kA	100kA	200kA
	480VAC	35kA	65kA	100kA
	600VAC	25kA	35kA	50kA
Frame 800		S	H	
	120VAC	65kA	100kA	
	240VAC	65kA	100kA	
	480VAC	50kA	65kA	
	600VAC	25kA	35kA	
Frame 1200		S	H	L
	120VAC	85kA	100kA	200kA
	240VAC	85kA	100kA	200kA
	480VAC	50kA	65kA	100kA
	600VAC	25kA	35kA	45Ka
Frame 2500		N/A	H	L
	120VAC	N/A	125kA	200kA
	240VAC	N/A	125kA	200kA
	480VAC	N/A	65kA	100kA
	600VAC	N/A	50kA	65Ka

Options available for all



Frame Sizes:
Auxiliary Contacts*
Alarm Contacts*
Shunt Trip Units *
Undervoltage Trip Units*

* 225 Frame must be Factory Installed



UL File No. All Frame Sizes E310239

UBW

Dimensions Frame 225

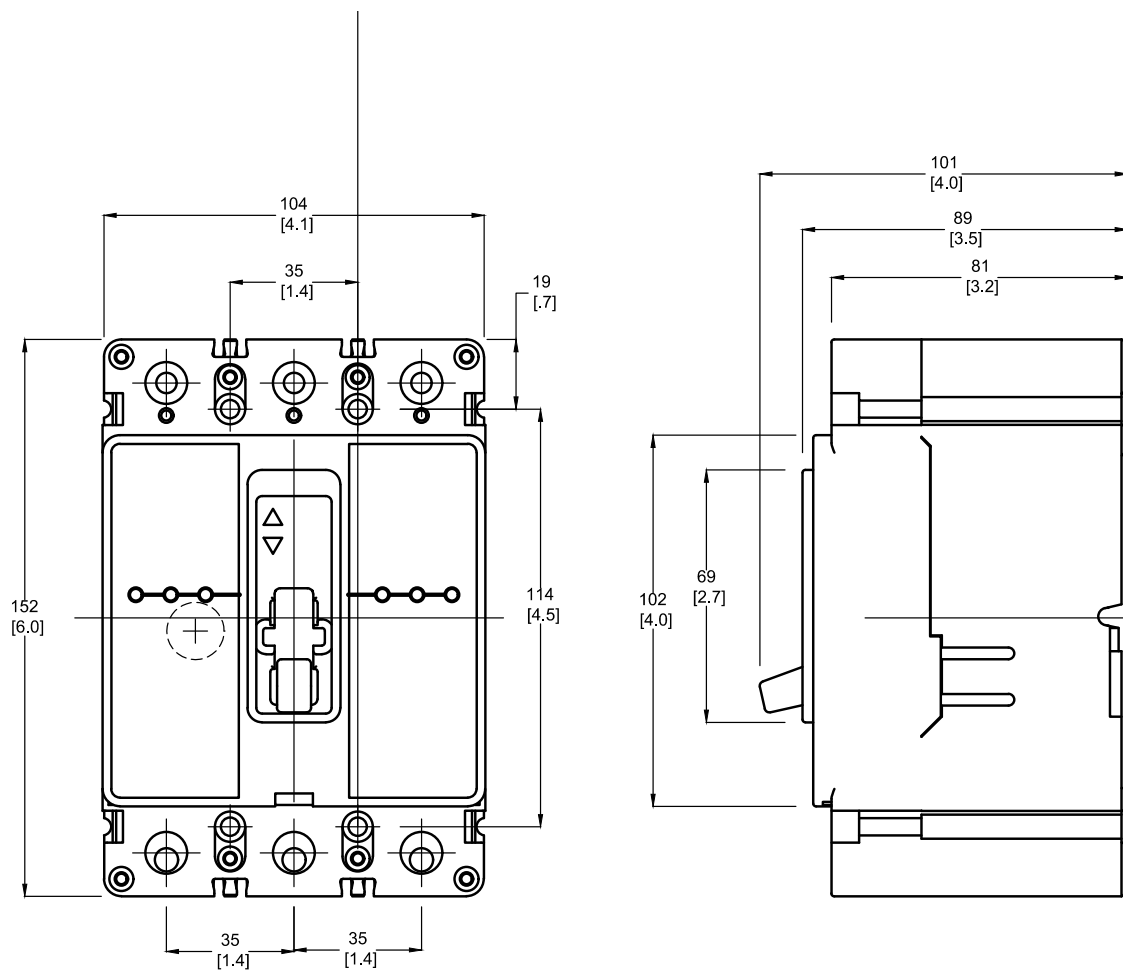
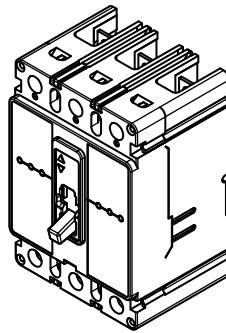


Dimensions Frame 225 - Flange Handle


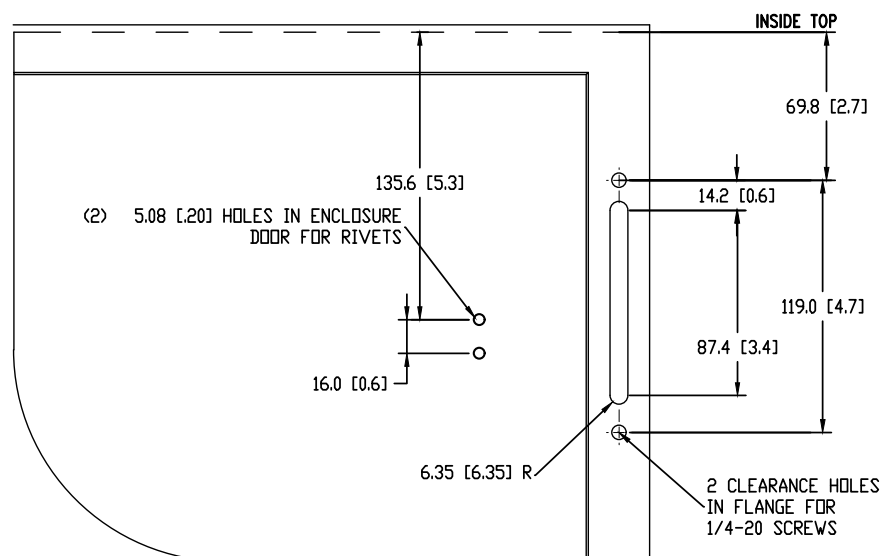
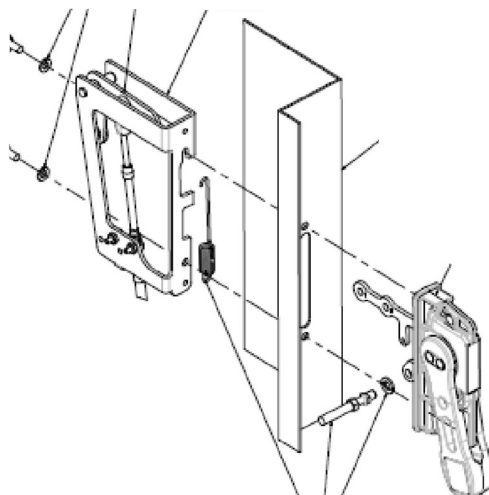


UBW

Dimensions Frame 225 - Rotary Handle

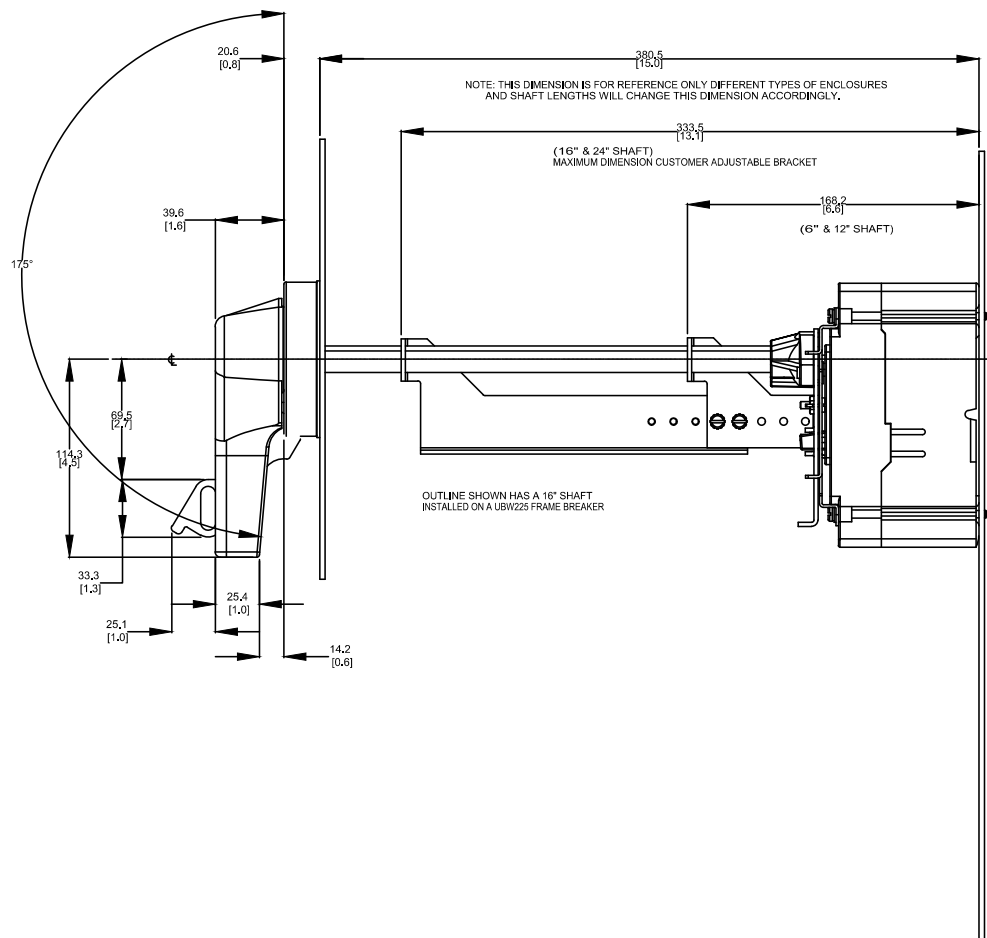
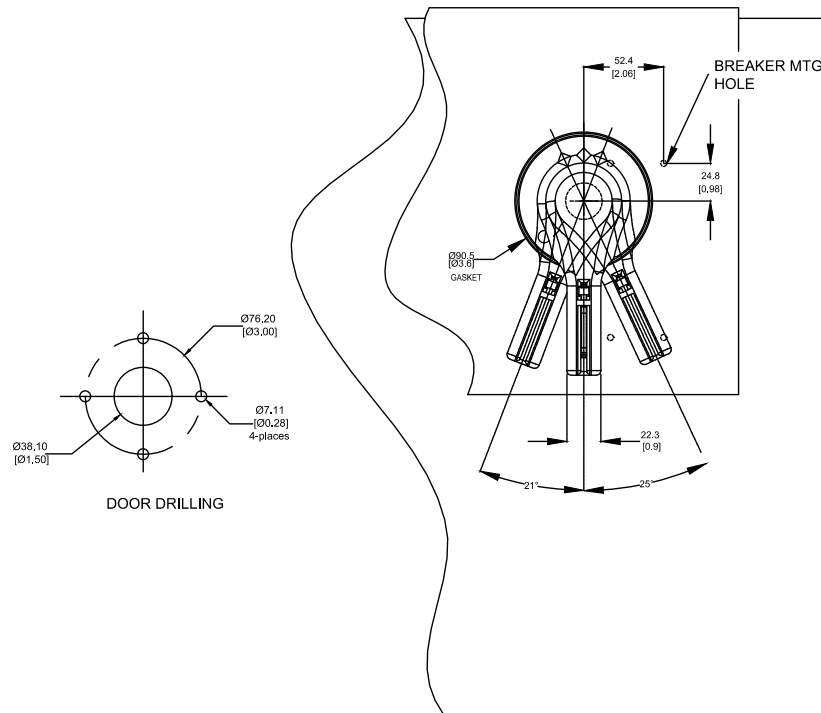


Dimensions Frame 250

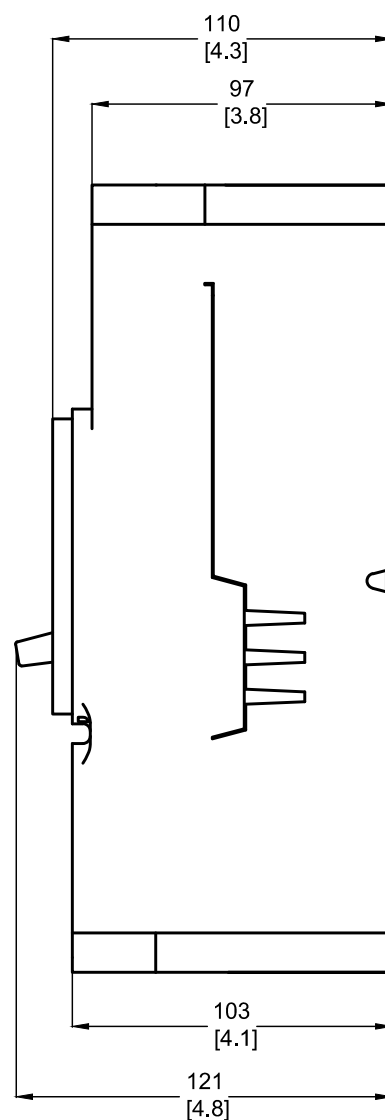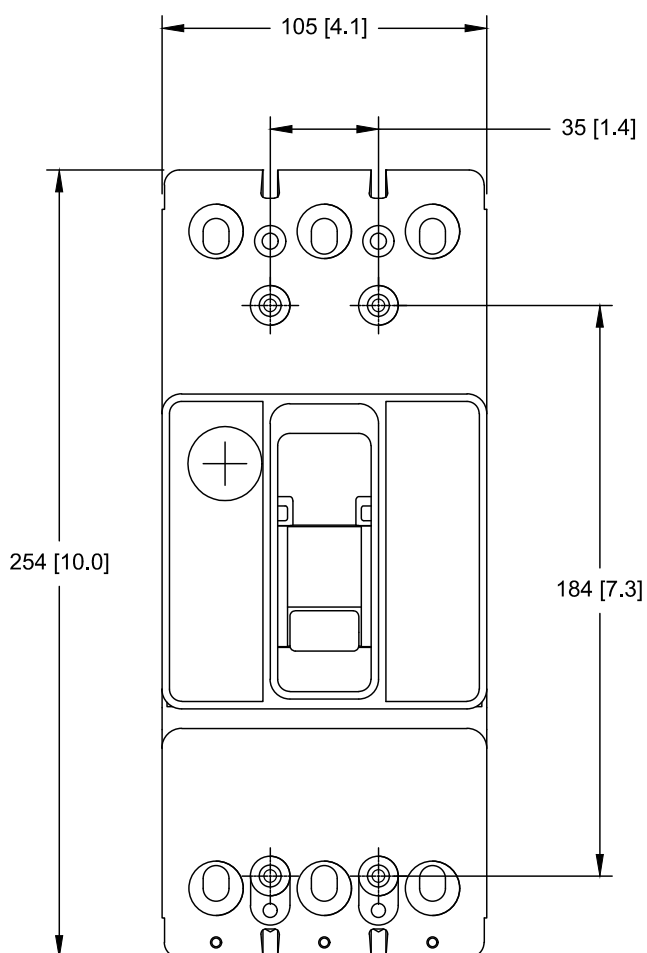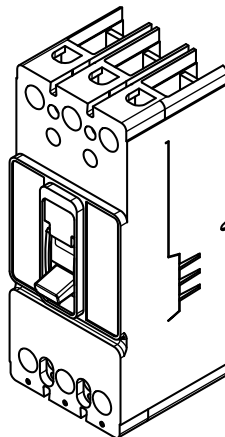


UBW

Dimensions Frame 250 - Flange Handle


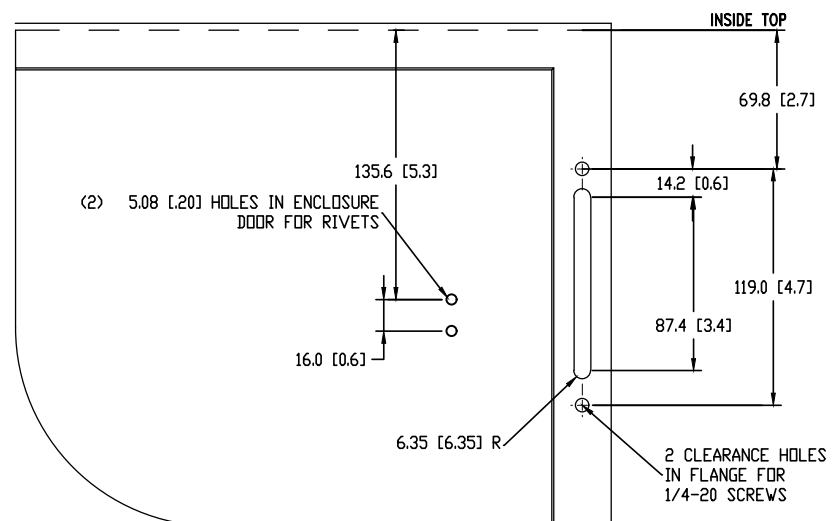
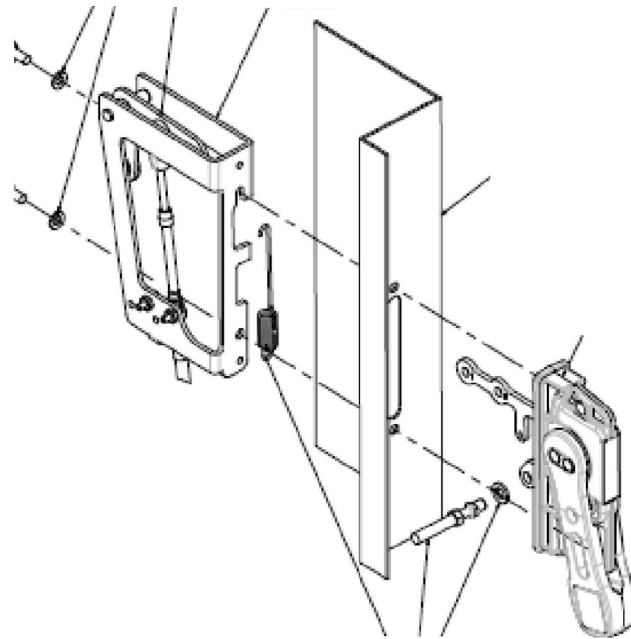


Dimensions Frame 250 - Rotary Handle


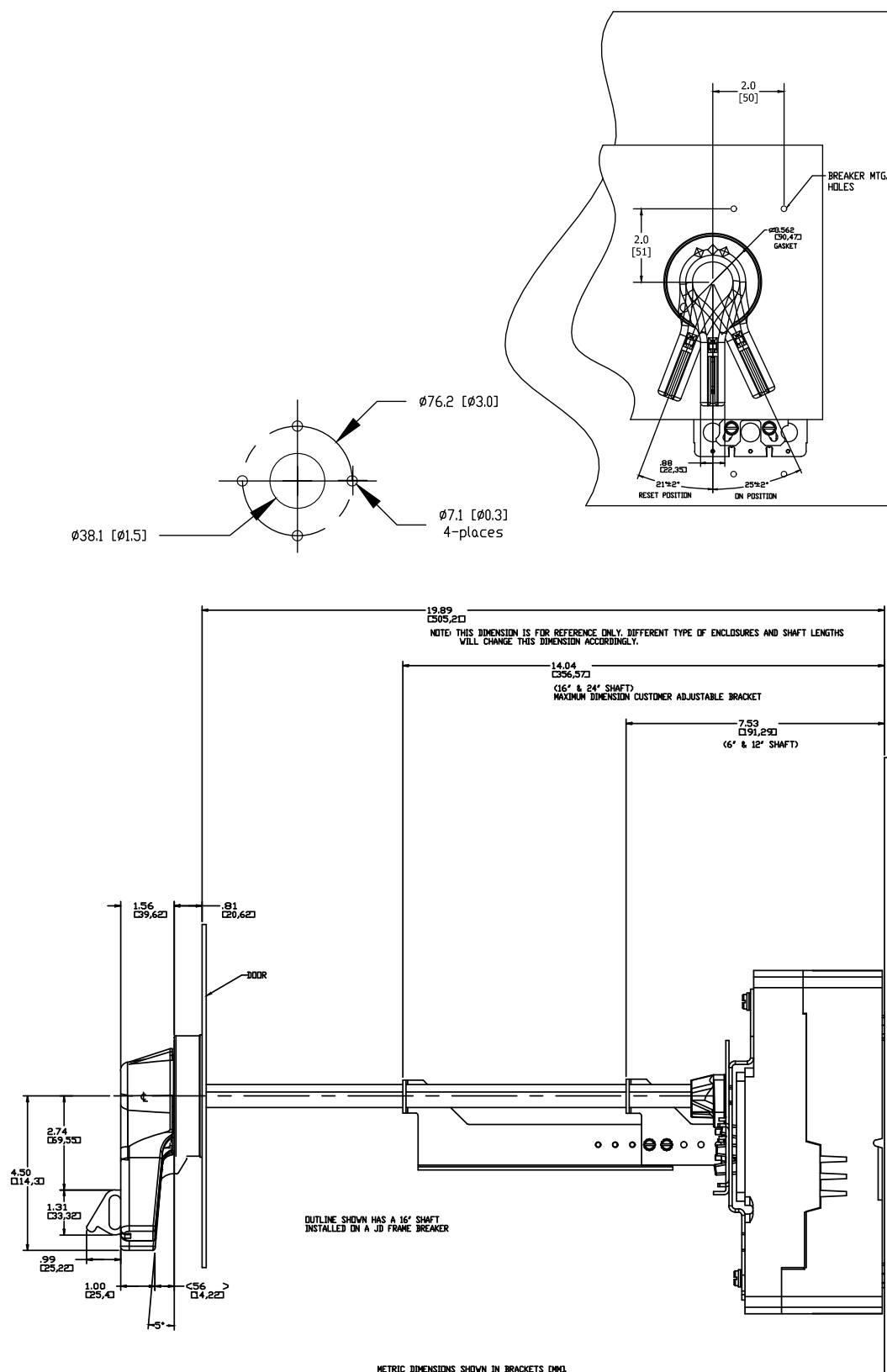


UBW

Dimensions Frame 400

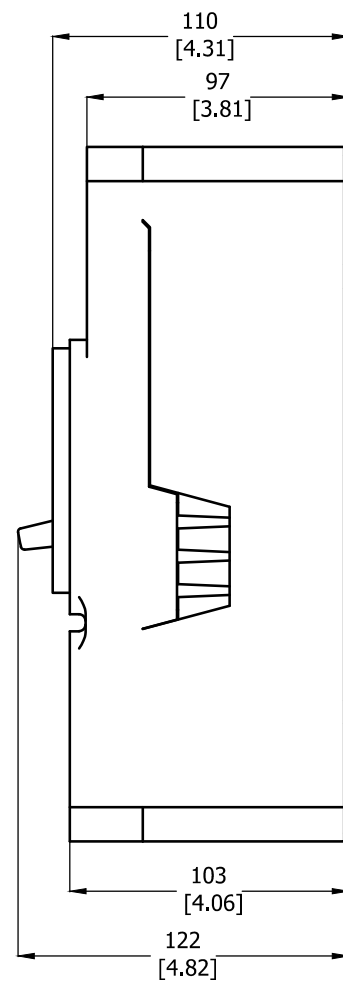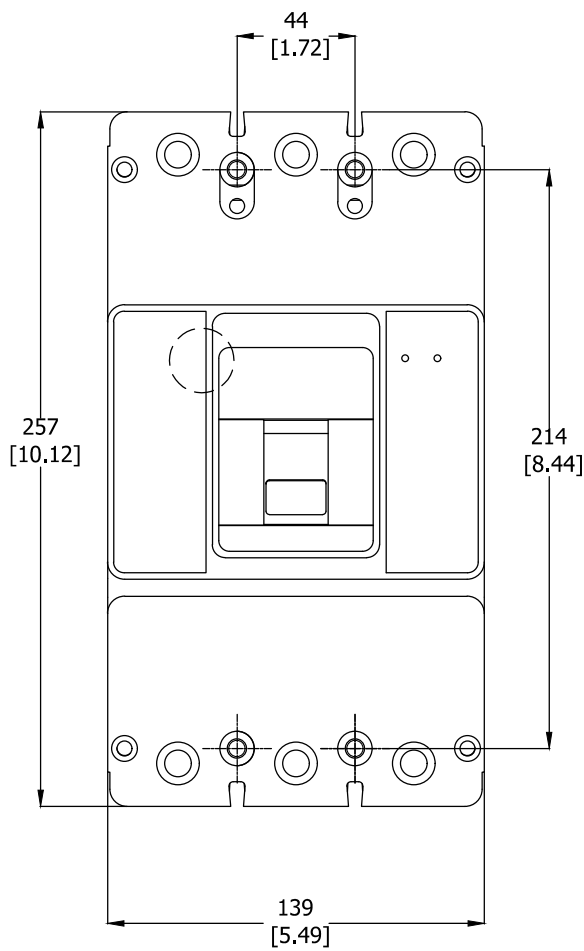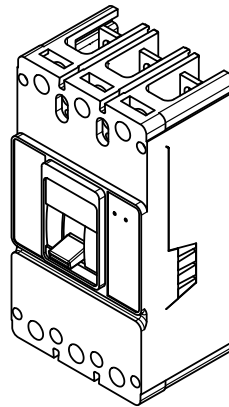



Dimensions Frame 400 - Flange Handle

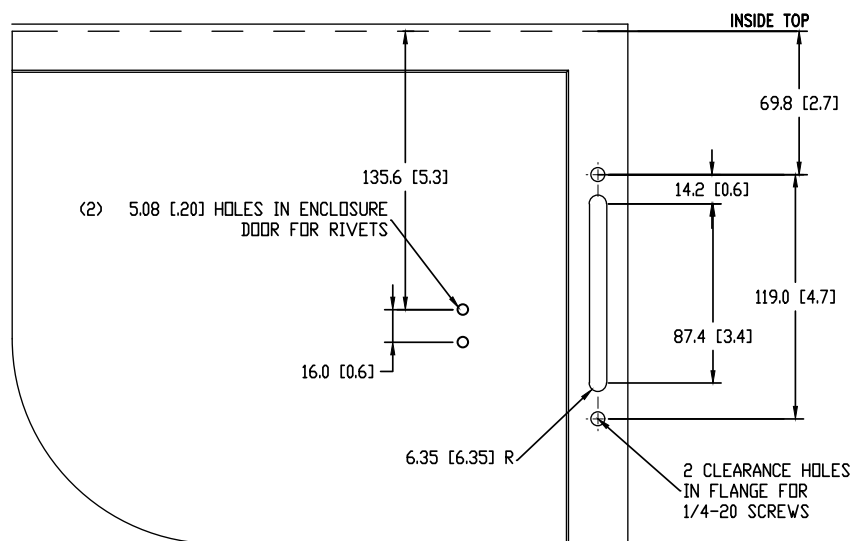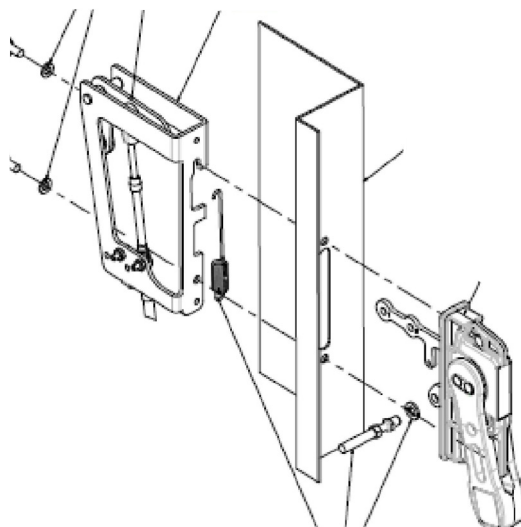

Dimensions Frame 400 - Rotary Handle





Dimensions Frame 600

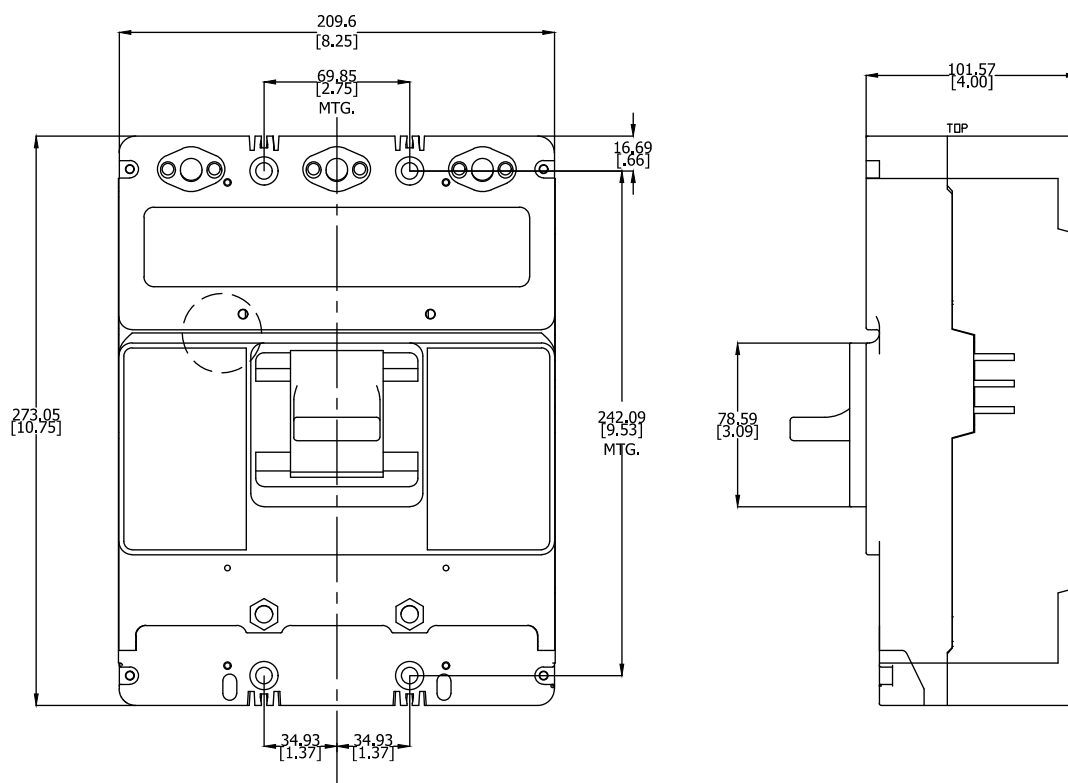
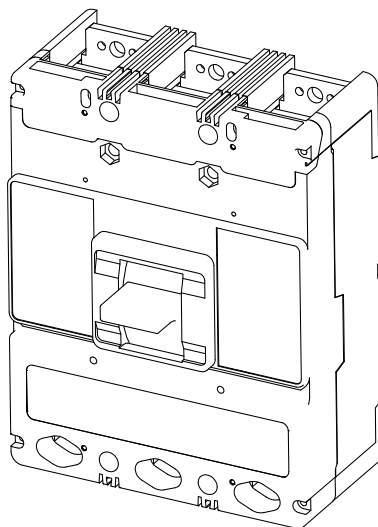


UBW

Dimensions Frame 600 - Flange Handle

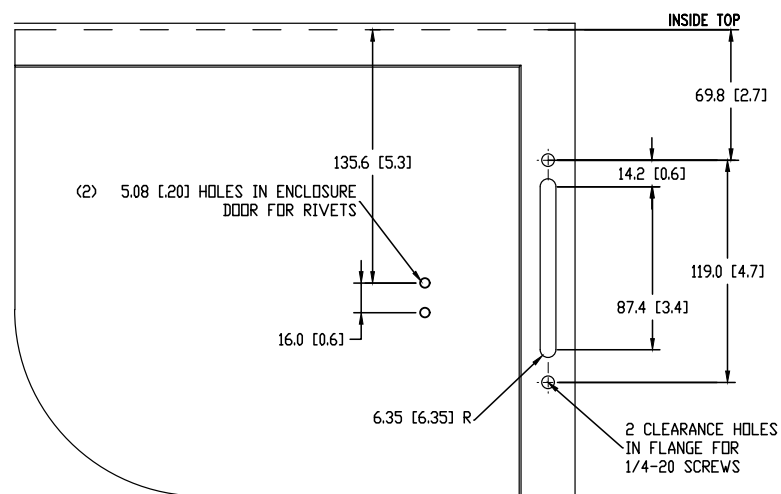
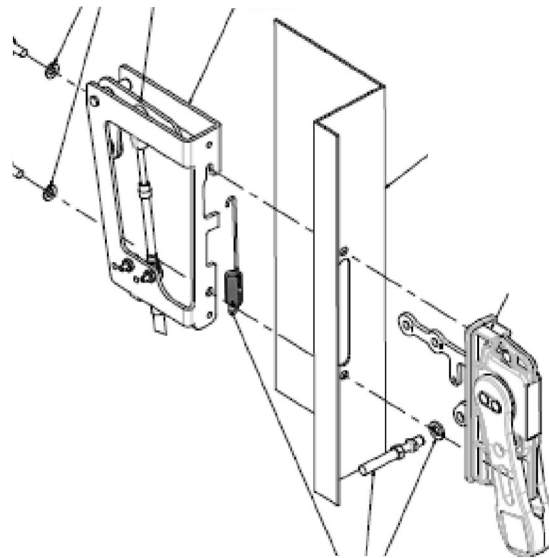


Dimensions Frame 600 - Rotary Handle

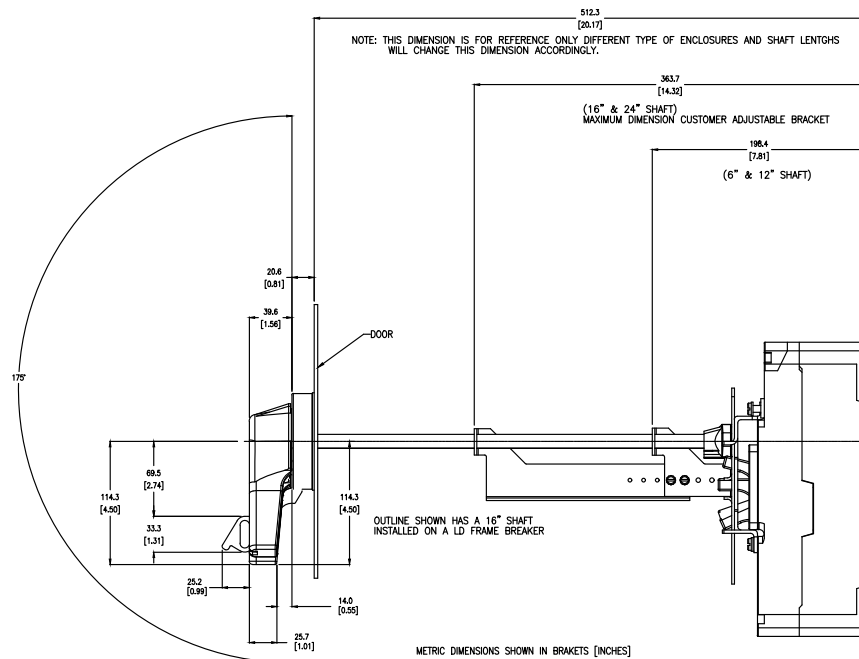
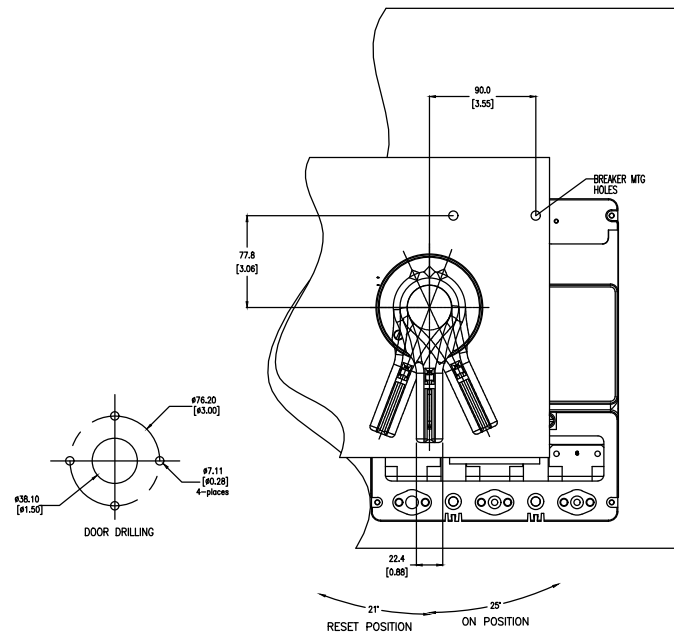


UBW

Dimensions Frame 800

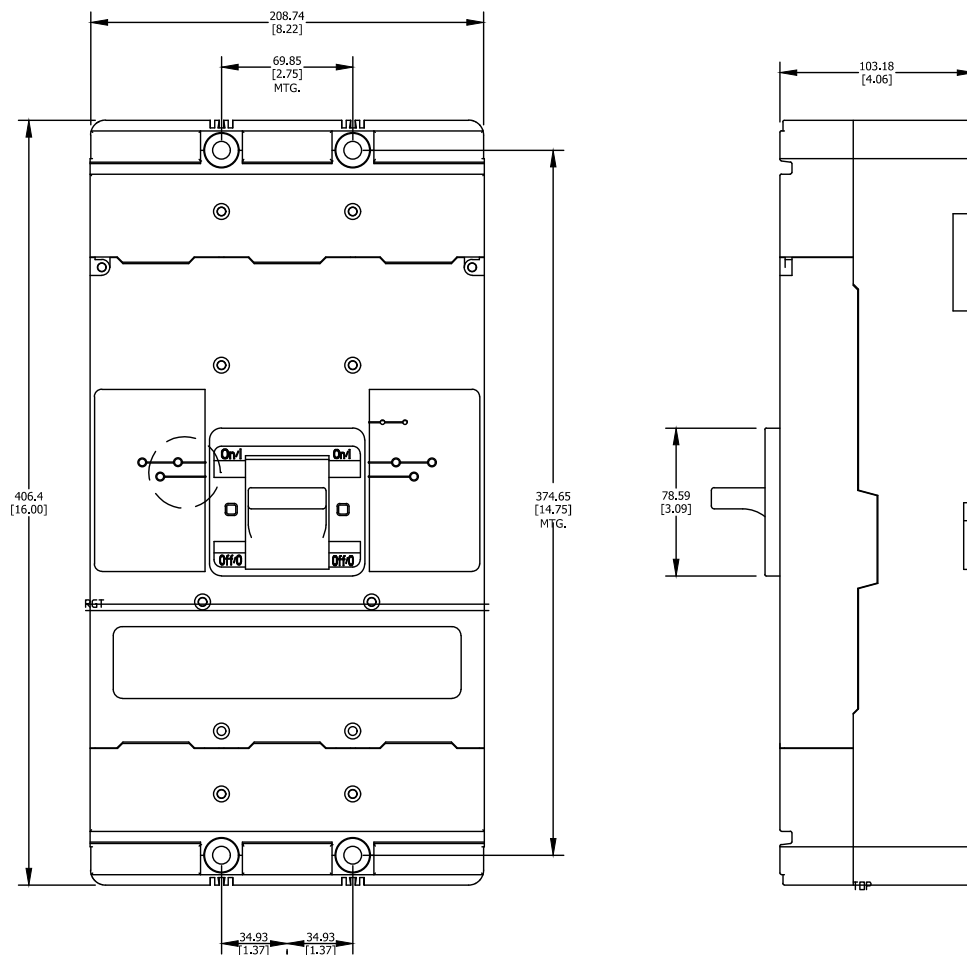
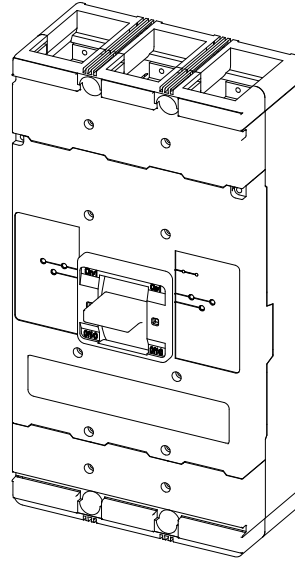


Dimensions Frame 800 - Flange Handle

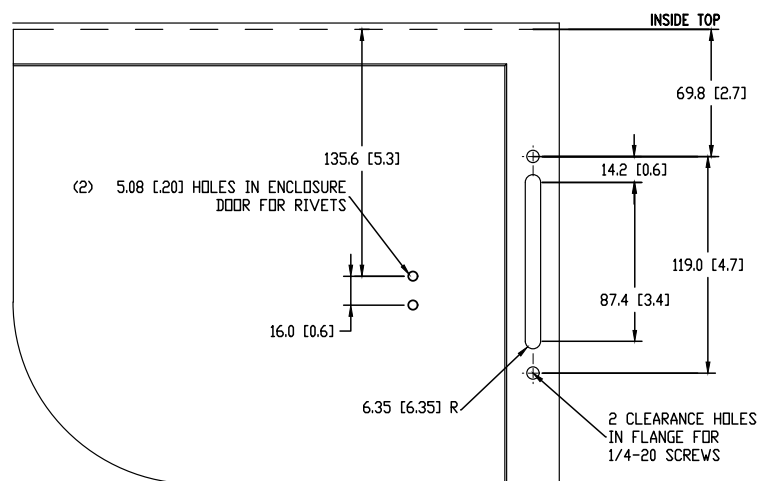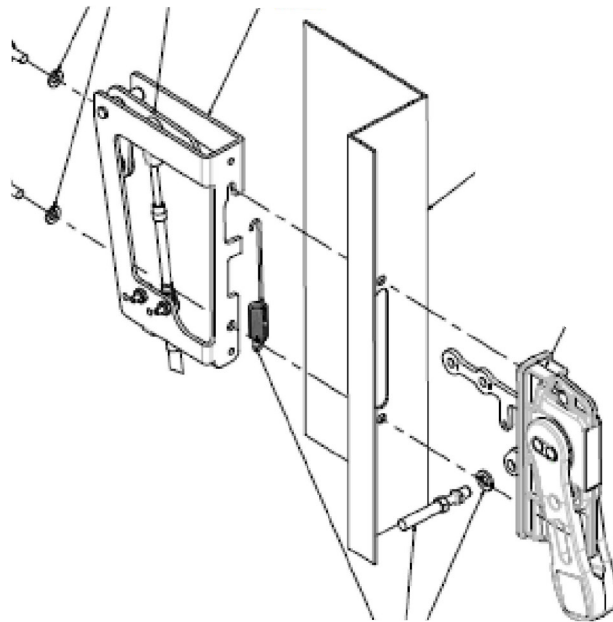




UBW

Dimensions Frame 800 - Rotary Handle

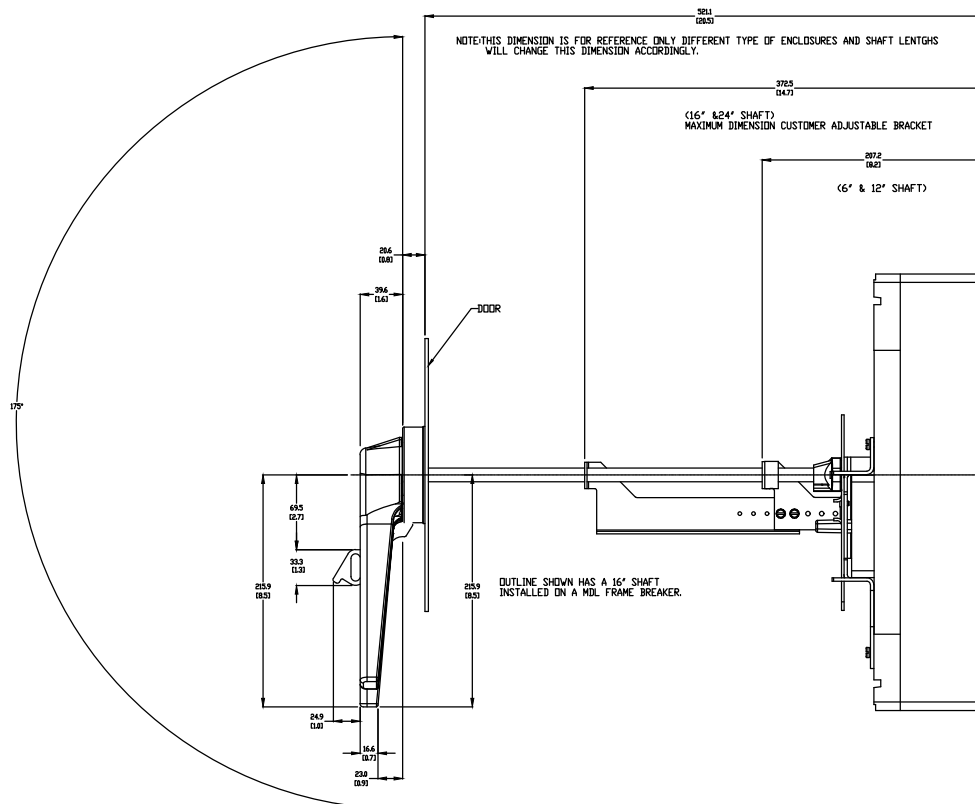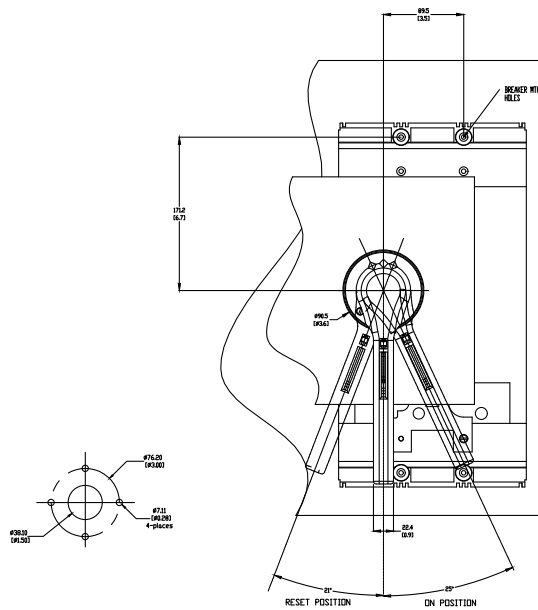



METRIC DIMENSIONS SHOWN IN BRACKETS (MM).

Dimensions Frame 1200

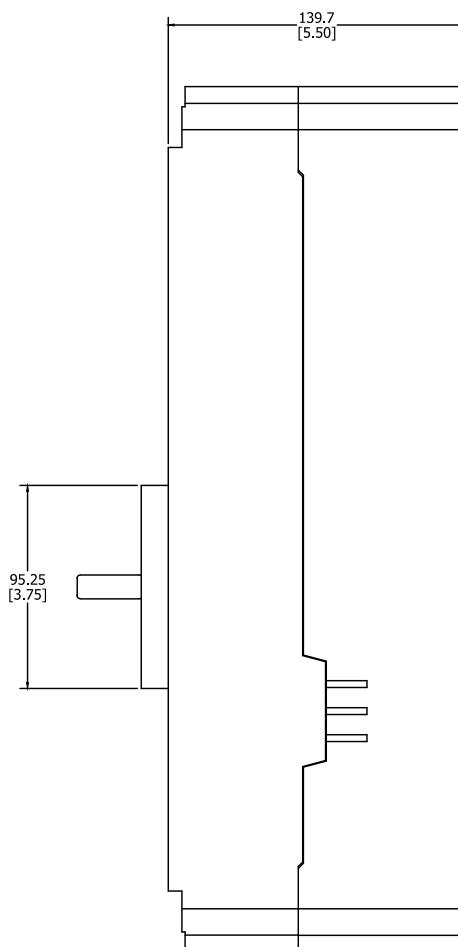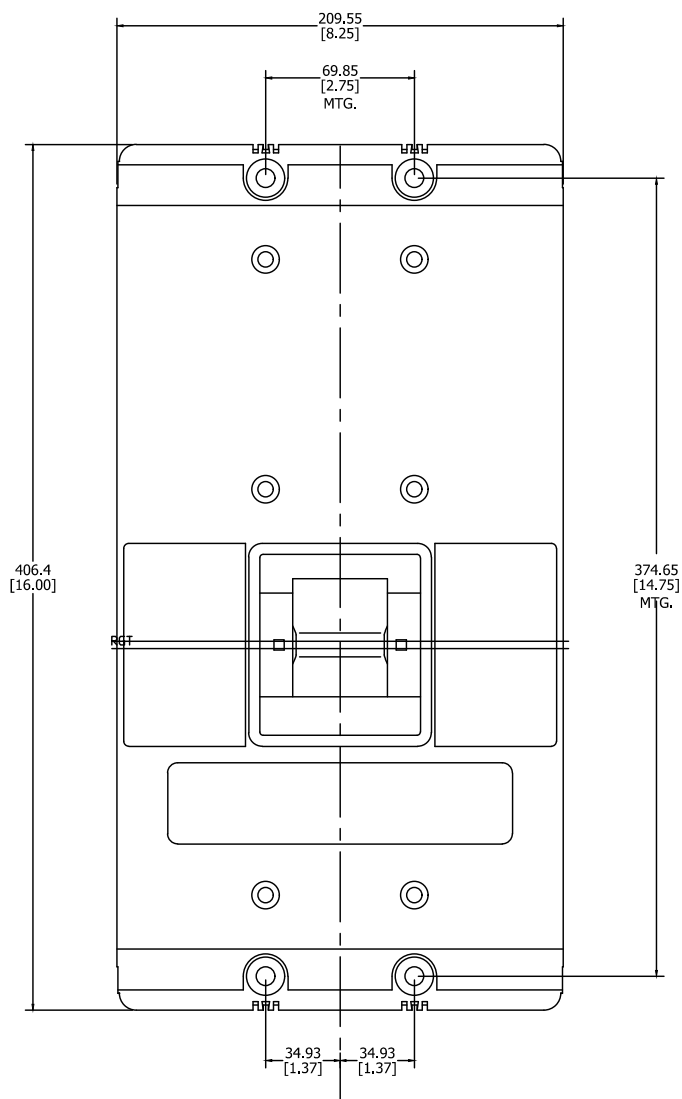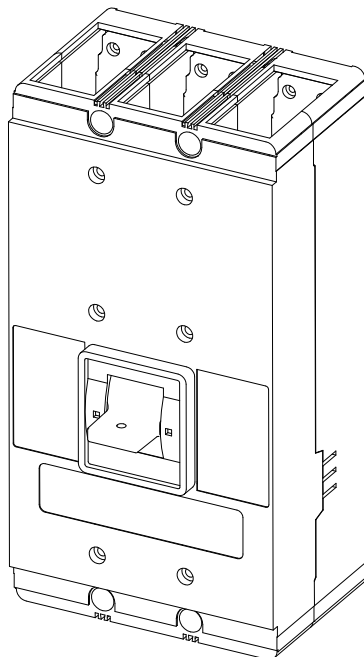


UBW


Dimensions Frame 1200 - Flange Handle

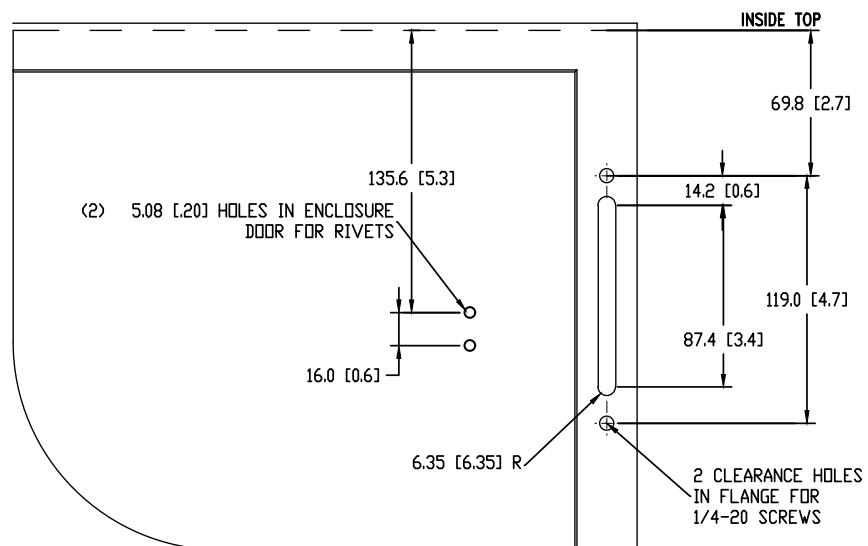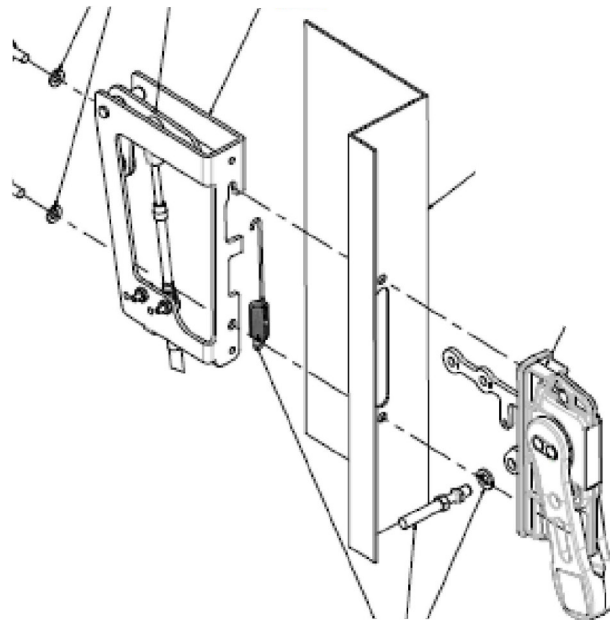

Dimensions Frame 1200 - Rotary Handle

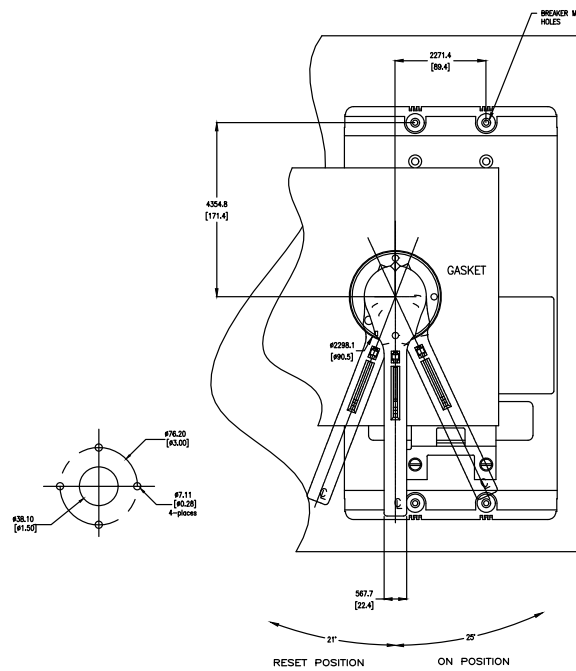


NOTE: THIS DIMENSION IS FOR REFERENCE ONLY DIFFERENT TYPE OF ENCLOSURES AND SHAFT LENGTHS WILL CHANGE THIS DIMENSION ACCORDINGLY.

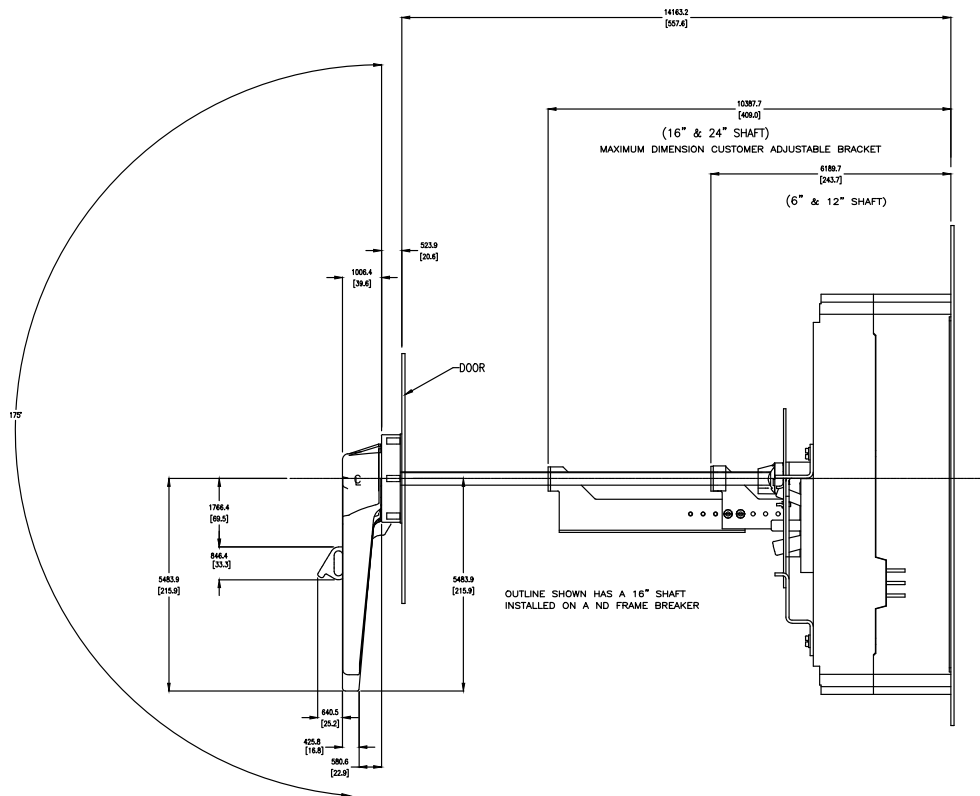


INCHES DIMENSIONS SHOWN IN BRACKETS

UBW

Dimensions Frame 2500

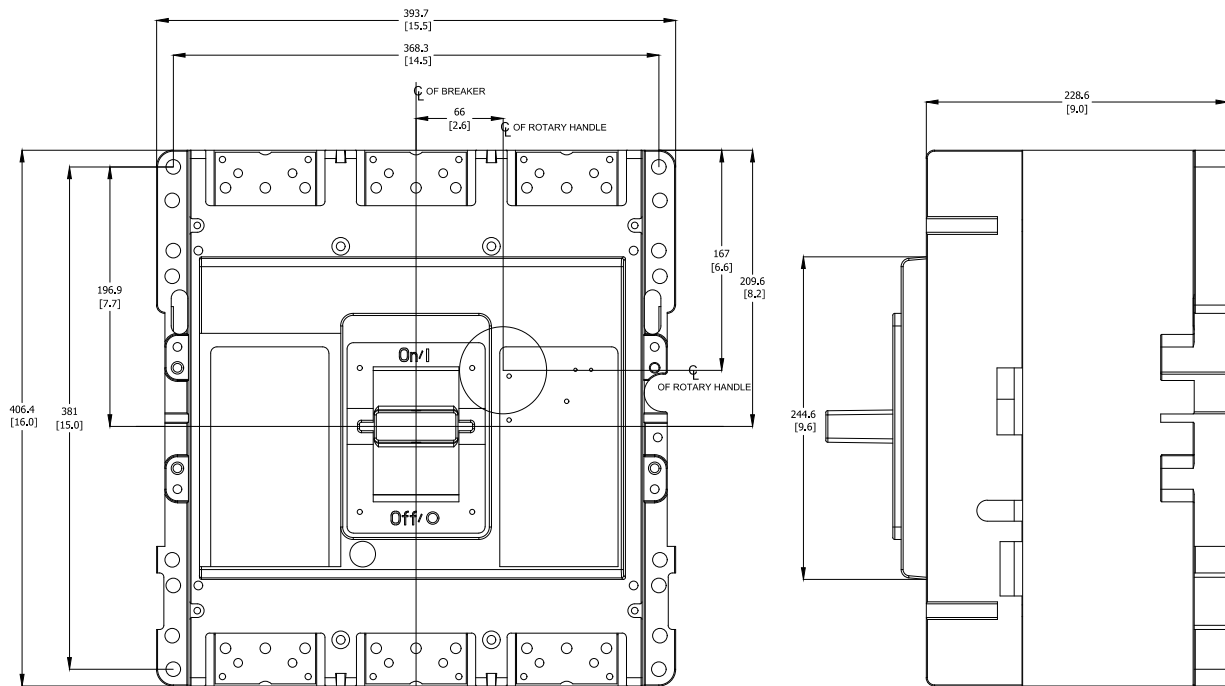

Dimensions Frame 2500 - Flange Handle

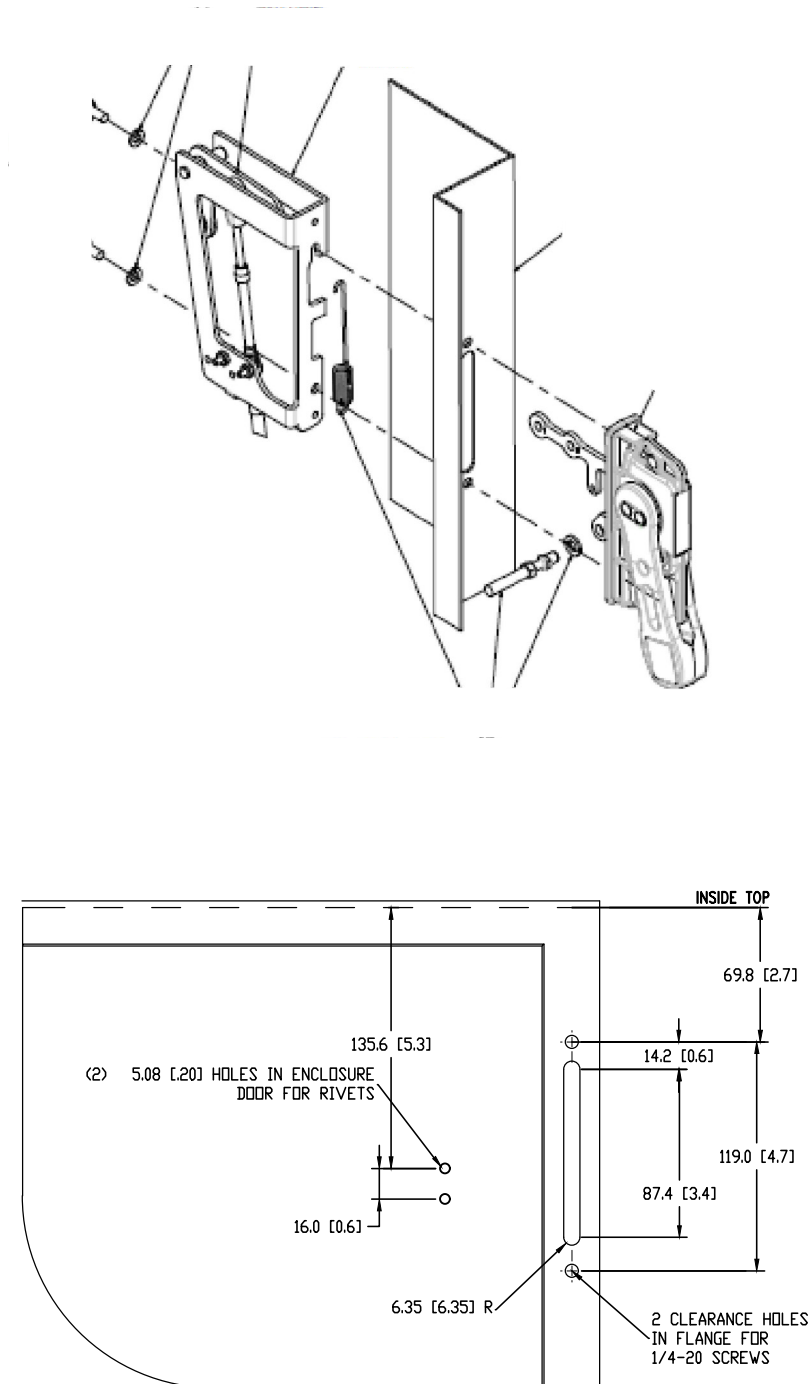

UBW

Internal Locations for Breaker Options

Frame 225			
	Left	Center	Right
Auxiliary Alarm			
Alarm			
Auxiliary/Alarm			
Shunt Trip			
Undervoltage Release			
		Applicable in indicated pole position	
		May be mounted left or right (not both)	

Frame 250			
	Left	Center	Right
Auxiliary Alarm			
Alarm			
Auxiliary/Alarm			
Shunt Trip			
Undervoltage Release			
		Applicable in indicated pole position	
		May be mounted left or right (not both)	

Frame 400			
	Left	Center	Right
Auxiliary Alarm			
Alarm			
Auxiliary/Alarm			
Shunt Trip			
Undervoltage Release			
		Applicable in indicated pole position	
		May be mounted left or right (not both)	

Frame 600			
	Left	Center	Right
Auxiliary Alarm			
Alarm			
Auxiliary/Alarm			
Shunt Trip			
Undervoltage Release			
		Applicable in indicated pole position	
		May be mounted left or right (not both)	

Frame 600			
	Left	Center	Right
Auxiliary Alarm			
Alarm			
Auxiliary/Alarm			
Shunt Trip			
Undervoltage Release			
		Applicable in indicated pole position	
		May be mounted left or right (not both)	

Frame 1200			
	Left	Center	Right
Auxiliary Alarm			
Alarm			
Auxiliary/Alarm			
Shunt Trip			
Undervoltage Release			
		Applicable in indicated pole position	
		May be mounted left or right (not both)	

Frame 2500			
	Left	Center	Right
Auxiliary Alarm			
Alarm			
Auxiliary/Alarm	N/A	N/A	N/A
Shunt Trip			
Undervoltage Release			
		Applicable in indicated pole position	
		May be mounted left or right (not both)	

ACW to UBW Cross Reference

ACW Breakers Part Number	Description	New UBW Part Number	Comments
ACW125P-FTU15-3	3 Pole 35ka@480vac 15amp	UBW225N-FTU15-3A	Fixed Thermal and Fixed Magnetic
ACW125P-FTU20-3	3 Pole 35ka@480vac 20amp	UBW225N-FTU20-3A	Fixed Thermal and Fixed Magnetic
ACW125P-FTU30-3	3 Pole 35ka@480vac 30amp	UBW225N-FTU30-3A	Fixed Thermal and Fixed Magnetic
ACW125P-FTU40-3	3 Pole 35ka@480vac 40amp	UBW225N-FTU40-3A	Fixed Thermal and Fixed Magnetic
ACW125P-FTU50-3	3 Pole 35ka@480vac 50amp	UBW225N-FTU50-3A	Fixed Thermal and Fixed Magnetic
ACW125P-FTU60-3	3 Pole 35ka@480vac 60amp	UBW225N-FTU60-3A	Fixed Thermal and Fixed Magnetic
ACW125P-FTU80-3	3 Pole 35ka@480vac 80amp	UBW225N-FTU80-3A	Fixed Thermal and Fixed Magnetic
ACW125P-FTU100-3	3 Pole 35ka@480vac 100amp	UBW225N-FTU100-3A	Fixed Thermal and Fixed Magnetic
ACW125P-FTU125-3	3 Pole 35ka@480vac 115amp	UBW225N-FTU125-3A	Fixed Thermal and Fixed Magnetic
ACW250P-FTU160-3	3 Pole 35ka@480vac 160amp	UBW225N-FTU150-3A	New UBW 150 Amp
ACW250P-FTU200-3	3 Pole 35ka@480vac 200amp	UBW225N-FTU200-3A	Adjustable Thermal and Fixed Magnetic
ACW250P-FTU250-3	3 Pole 35ka@480vac 250amp	UBW250N-FTU250-3A	Adjustable Thermal and Fixed Magnetic
ACW400P-FTU300-3	3 Pole 35ka@480vac 300amp	UBW400N-FTU300-3A	Adjustable Thermal and Fixed Magnetic
ACW400P-FTU400-3	3 Pole 35ka@480vac 400amp	UBW400N-FTU400-3A	Adjustable Thermal and Fixed Magnetic
ACW800P-FTU500-3	3 Pole 35ka@480vac 500amp	UBW600N-FTU500-3A	Adjustable Thermal and Fixed Magnetic
ACW800P-FTU600-3	3 Pole 35ka@480vac 600amp	UBW600N-FTU600-3A	Adjustable Thermal and Fixed Magnetic
ACW800P-FTU800-3	3 Pole 35ka@480vac 800amp	UBW800S-FTU800-3A	New UBW 50KA
ACW125W-FTU15-3	3 Pole 65ka@480vac 15amp	UBW225H-FTU15-3A	Fixed Thermal and Fixed Magnetic
ACW125W-FTU20-3	3 Pole 65ka@480vac 20amp	UBW225H-FTU20-3A	Fixed Thermal and Fixed Magnetic
ACW125W-FTU30-3	3 Pole 65ka@480vac 30amp	UBW225H-FTU30-3A	Fixed Thermal and Fixed Magnetic
ACW125W-FTU40-3	3 Pole 65ka@480vac 40amp	UBW225H-FTU40-3A	Fixed Thermal and Fixed Magnetic
ACW125W-FTU50-3	3 Pole 65ka@480vac 50amp	UBW225H-FTU50-3A	Fixed Thermal and Fixed Magnetic
ACW125W-FTU60-3	3 Pole 65ka@480vac 60amp	UBW225H-FTU60-3A	Fixed Thermal and Fixed Magnetic
ACW125W-FTU80-3	3 Pole 65ka@480vac 80amp	UBW225H-FTU80-3A	Fixed Thermal and Fixed Magnetic
ACW125W-FTU100-3	3 Pole 65ka@480vac 100amp	UBW225H-FTU100-3A	Fixed Thermal and Fixed Magnetic
ACW125W-FTU125-3	3 Pole 65ka@480vac 115amp	UBW225H-FTU125-3A	Fixed Thermal and Fixed Magnetic
ACW250W-FTU160-3	3 Pole 65ka@480vac 160amp	UBW225H-FTU150-3A	New UBW 150 Amp
ACW250W-FTU200-3	3 Pole 65ka@480vac 200amp	UBW225H-FTU200-3A	Adjustable Thermal and Fixed Magnetic
ACW250W-FTU250-3	3 Pole 65ka@480vac 250amp	UBW250H-FTU250-3A	Adjustable Thermal and Fixed Magnetic
ACW400W-FTU300-3	3 Pole 65ka@480vac 300amp	UBW400H-FTU300-3A	Adjustable Thermal and Fixed Magnetic
ACW400W-FTU400-3	3 Pole 65ka@480vac 400amp	UBW400H-FTU400-3A	Adjustable Thermal and Fixed Magnetic
ACW800W-FTU500-3	3 Pole 65ka@480vac 500amp	UBW600H-FTU500-3A	Adjustable Thermal and Fixed Magnetic
ACW800W-FTU600-3	3 Pole 65ka@480vac 600amp	UBW600H-FTU600-3A	Adjustable Thermal and Fixed Magnetic
ACW800W-FTU800-3	3 Pole 65ka@480vac 800amp	UBW800H-FTU800-3A	Adjustable Thermal and Fixed Magnetic

WEG's scope of solutions is not limited to the products and solutions presented in this brochure.

Contact WEG for information on additional products and solutions.

For WEG's worldwide operations visit our website



www.weg.net



 **1-800-ASK-4WEG**

 **info-us@weg.net**

 **Duluth, GA**