




# Hydraulic Pump Motors

Specially designed for higher versatility

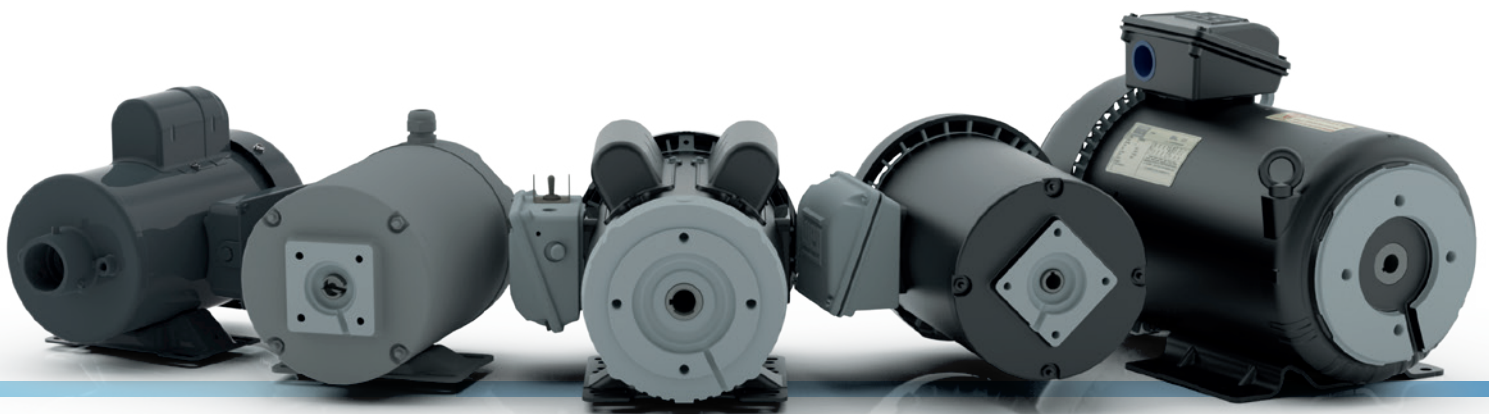

# Features

## Product scope

- Three-phase and single-phase
- Frame: 42, 48, 56, 182/4T, 213/5T, 254/6T
- Voltage: 115/230, 230, 127, 127/220, 220, 208-230/460 V
- Output: 1/2 HP up to 20 HP
- Number of poles: 2 or 4 Pole
- Frequency: 50, 60 or 50/60Hz
- Shaft: Spline / Tang / Keyed (female)
- Enclosure: TEFC, ODP or TENV
- Insulation: Class F

## Certification

- UL/CSA
- CE Under request (declaration)

## Flange



Hub Mount  
(Frame 48)



NEMA 4F-17  
(Frames 42 to 56)



SAE A-A  
(Frames 48 and 56)



SAE A  
(Frames 48 to 213/5T)




SAE B  
(Frame 254/6T)

# Application

WEG counts on wide range of motors specially designed for application on hydraulic pumps.  
**Contact us.**



Hydraulic lift table

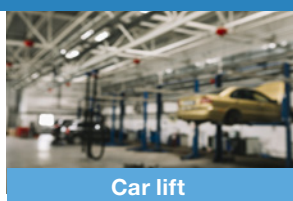

Car lift



Hydraulic power pack



Oil circulating pump



+1 678 2492000

info-us@weg.net

Duluth - Georgia - US

www.weg.net